


Bemerkung:

- ① Übersetzungsverhältnis "003" nicht mit Betriebsart "S5-Zyklusbetrieb" lieferbar
 Übersetzungsverhältnis "050" nicht mit Betriebsart "S1-Dauerbetrieb" lieferbar
- ② Abtriebswelle "C" und "D" nicht mit Betriebsart "S1-Dauerbetrieb" lieferbar
- ③ nur für Motoren mit Flüssigkeitskühlung
- ④ nur für Motoren ohne Flüssigkeitskühlung

Zulässige Kombinationen

Einbaulage Betriebsart	mögliche Übersetzungen		eingegängtes Getriebeumkehrspiel
	einstufig	zweistufig	
CO	3, 4, 5, 7, 10	20	Nein
MO	4, 5, 7, 10	20, 50	Ja
VO	4, 5, 7, 10	20, 50	Ja

Bildbeispiel: Planetengetriebe

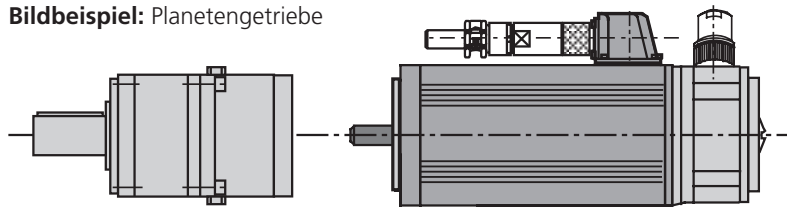

Planetengetriebe

Motor


Note:

- ① Transmission ratio "003" not available with operating mode "S5 cycle mode"
 Transmission ratio "050" not available with operating mode "S1 continuous duty"
- ② Driven shaft "C" and "D" not available with operating mode "S1 continuous duty"
- ③ only for motors with liquid cooling
- ④ only for motors without liquid cooling

Permissible combinations

mounting orientation and operating mode	possible transmissions		restricted gear reversal
	single stage	two stage	
CO	3, 4, 5, 7, 10	20	No
MO	4, 5, 7, 10	20, 50	Yes
VO	4, 5, 7, 10	20, 50	Yes

Illustration example: Planetary gearbox

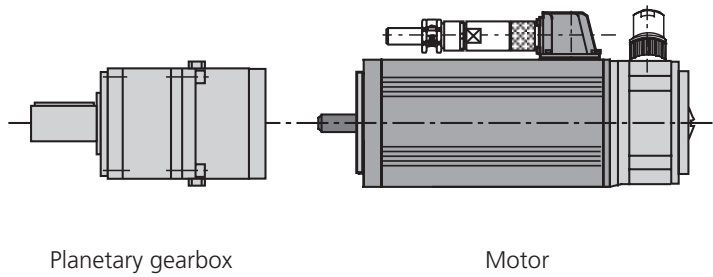

Planetary gearbox

Motor