

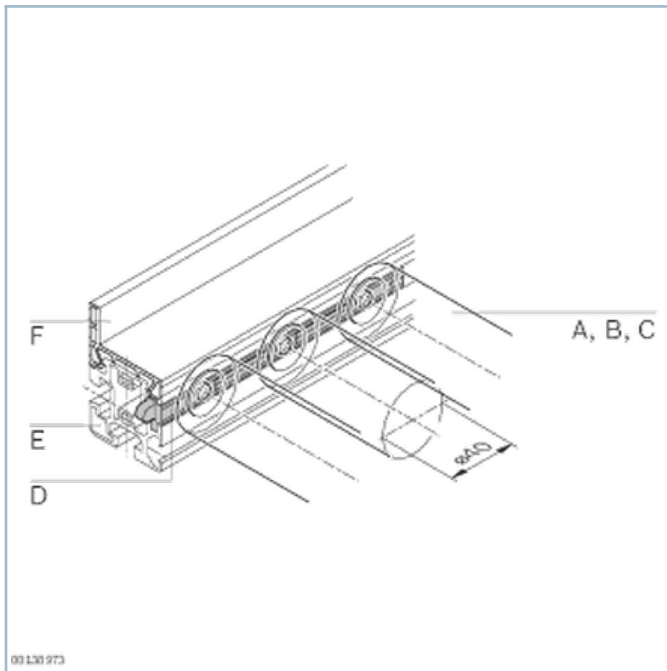
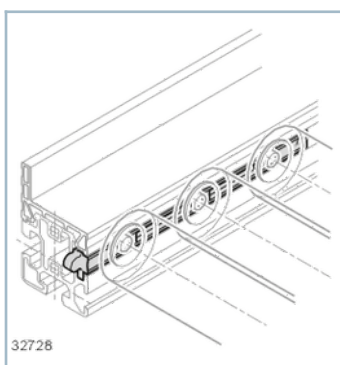




Roller carrier, roller mount, roller

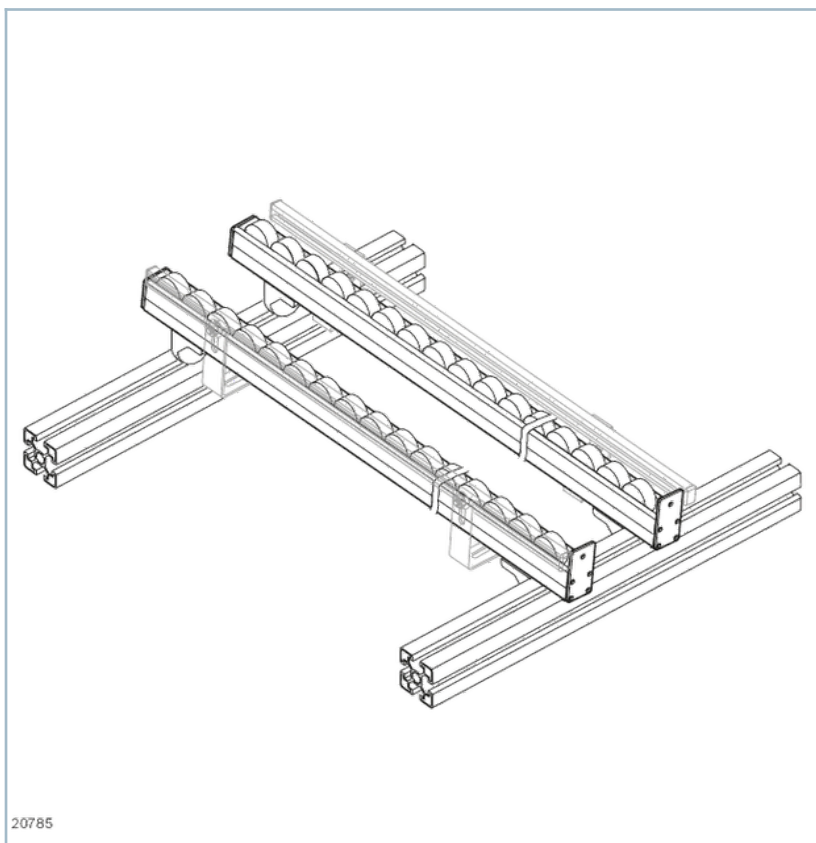

- Based on EcoFlow section profile
- For manual slide sections with rollers
- Clip-in guide profiles with lateral guide and clip-in conveyor rollers


Product description

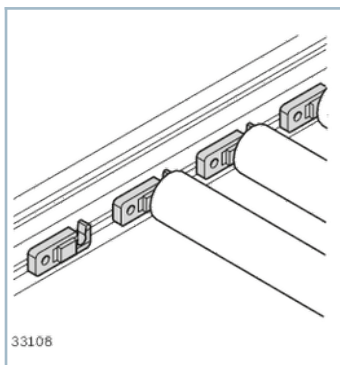

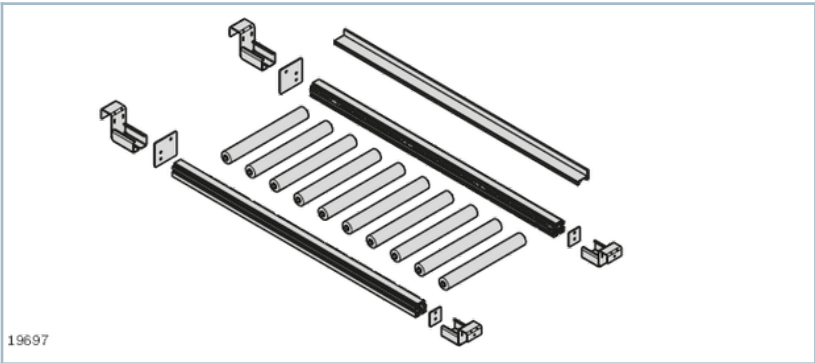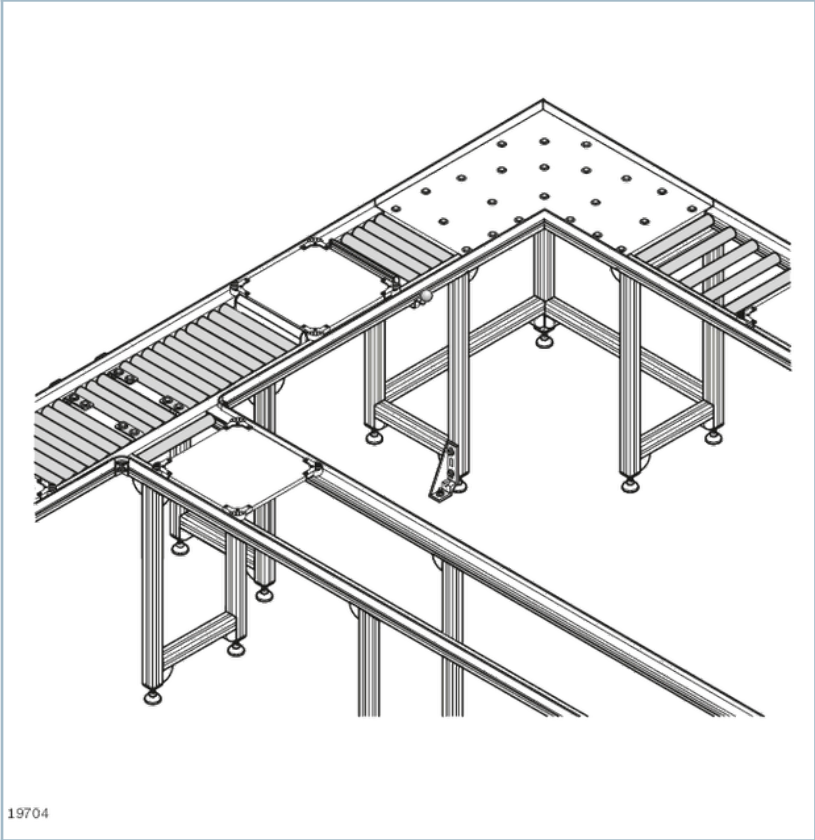


Technical data

EcoFlow roller

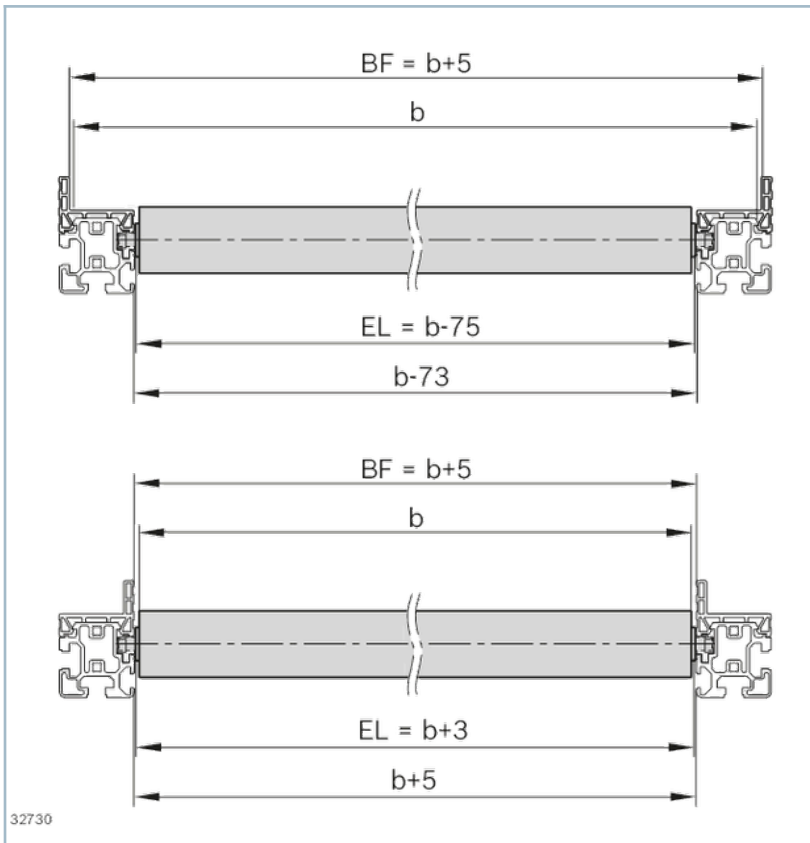


Dimensions


EcoFlow roller, plastic, steel, galvanized, stainless steel

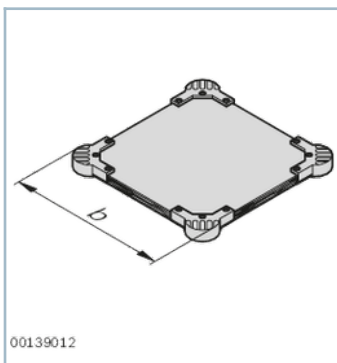


EcoFlow roller, plastic, steel, galvanized, stainless steel

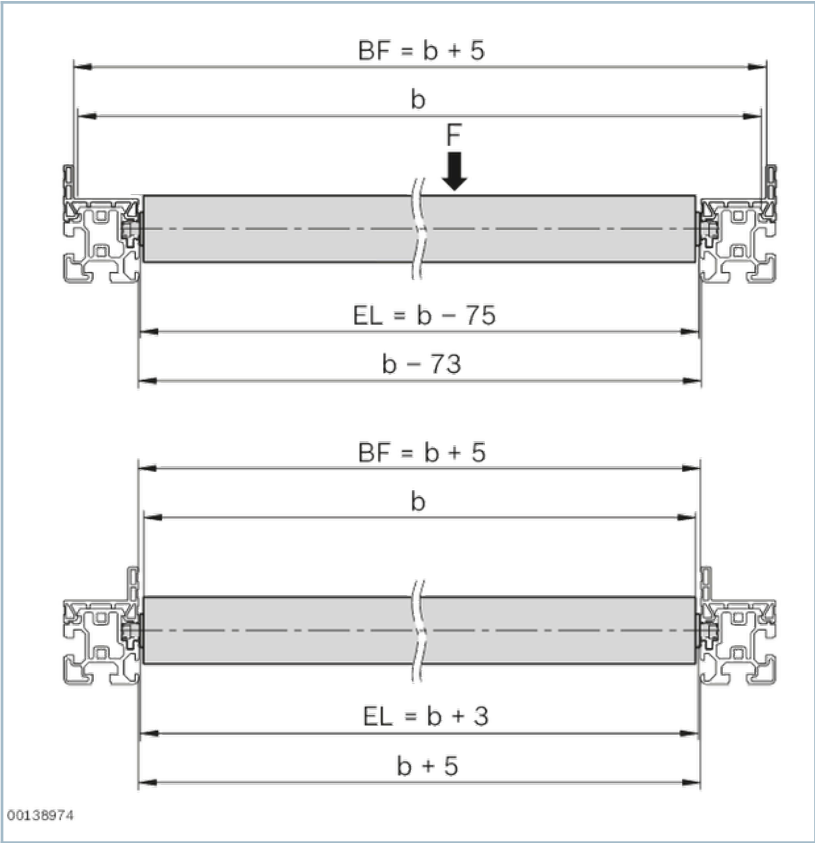

EcoFlow roller

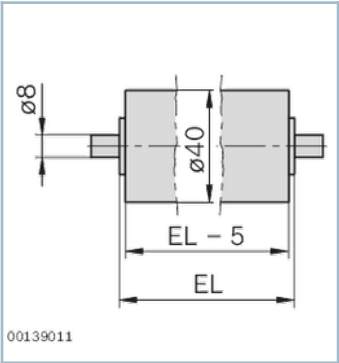




Roller mount slot 8, slot 10

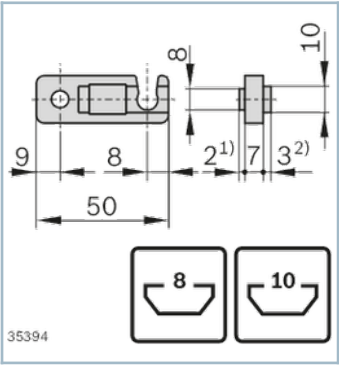






8 mm slot

10 mm slot

Roller mount slot 8r, slot 10

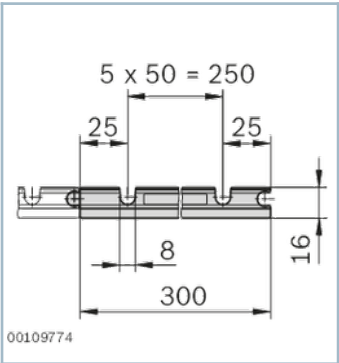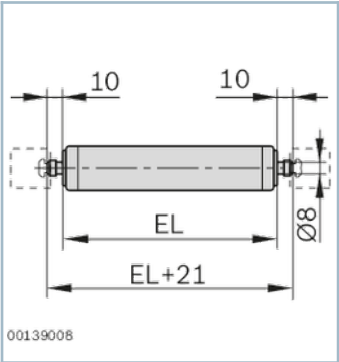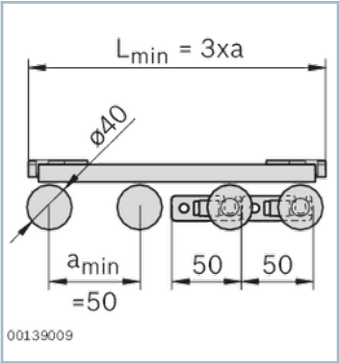

Delivery notes

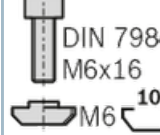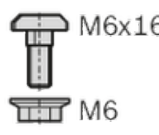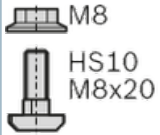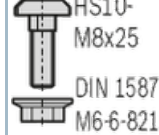 FS1	FS2	FS3	FS4	FS5	FS6	FS7	FS8
 DIN 7984 M6x12 	 DIN 7984 M6x16 	 M6x16 	 M8 HS10 M8x20 	 HS10- M8x25 DIN 1587- M6-6-82169 	 6-FST 	 W193- M8-10 	 DIN 7500 EE M6x30 

Ordering codes

	F _{max}	EL	Groove		ESD	No.
	N	mm				
EcoFlow roller – steel, galvanized, EL = 225	500	225				3842525737
EcoFlow roller – steel, galvanized, EL = 325	500	325				3842525738
EcoFlow roller – steel, galvanized, EL = 425	500	425				3842525739
EcoFlow roller – plastic, EL = 225	150	225				3842525740
EcoFlow roller – plastic, EL = 325	150	325				3842525741
EcoFlow roller – plastic, EL = 425	150	425				3842525742
Roller mount, 8 mm slot			8	1		3842535667
Roller mount, 10 mm slot			10	1		3842535668
EcoFlow roller carrier				1 0		3842535683
EcoFlow roller – steel, galvanized, EL = 525	500	525				3842537163
EcoFlow roller – plastic, EL = 525	150	525				3842537164
EcoFlow roller – steel, galvanized, EL = 105...1005	500	105 ... 1005				3842994988
EcoFlow roller – plastic, EL = 105...1005	150	105 ... 605				3842994989
EcoFlow roller – stainless steel, EL = 105...1005	150	105 ... 1005				3842995008