

Strut profile 30x45°



Product description

[Quick & Easy profile finishes](#)

[Introduction to strut profiles](#)

Technical data

[Quick & Easy profile finishes](#)


Dimensions

Strut profile 30x45°

30x45°

$A = 4,0 \text{ cm}^2$
 $I_x = 3,6 \text{ cm}^4$
 $I_y = 5,1 \text{ cm}^4$
 $W_x = 2,1 \text{ cm}^3$
 $W_y = 2,3 \text{ cm}^3$
 $I_t = 2,1 \text{ cm}^4$
 $W_t = 2,4 \text{ cm}^3$
 $m = 1,1 \text{ kg/m}$

19184

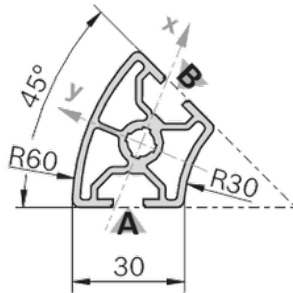

Ordering codes

The following cover caps can be used:

Cover cap 30x45°, signal gray (1x)

Cover cap 30x45°, black (1x)

	L			ESD	No.
	mm				
Strut profile 30x45°	50 ... 6070		1		3842993011
Strut profile 30x45° 20xL=5600mm	5600	20			3842524034
Strut profile 30x45° Q&E	50 ... 6070		1		3842993711
Cover cap 30x45°, black ESD			20		3842551011
Cover cap 30x45°, signal gray			20		3842551010
Strut profile 30x45°	6070		1		3842558314

Standard profile finishing Lmax = 6000 mm (note minimum length)		M8
---	--	----